
 




Selection and ordering data


CLASS 10, up to 70 Amps
3RV17 UL 489 Circuit Breaker

Rated current	Current setting range (FLA) Thermal overload release	Instantaneous short-circuit release	Screw connection		Weight approx. kg
			Order No.	List Price \$	
I_n A	 A	 A			
Size S3 2)					
10	10	150	3RV1742-5AD10	832.00 ea.	2.1
15	15	225	3RV1742-5BD10	832.00 ea.	
20	20	260	3RV1742-5CD10	832.00 ea.	
25	25	325	3RV1742-5DD10	832.00 ea.	
30	30	390	3RV1742-5ED10	832.00 ea.	
35	35	455	3RV1742-5FD10	832.00 ea.	
40	40	520	3RV1742-5GD10	832.00 ea.	
45	45	585	3RV1742-5HD10	832.00 ea.	
50	50	650	3RV1742-5JD10	832.00 ea.	
60	60	780	3RV1742-5LD10	832.00 ea.	
70	70	910	3RV1742-5PD10	832.00 ea.	



Note: Short Circuit Ratings: 18 kA at 600Y/347V
35 kA at 480Y/277V

Dimensions - 3RV1742

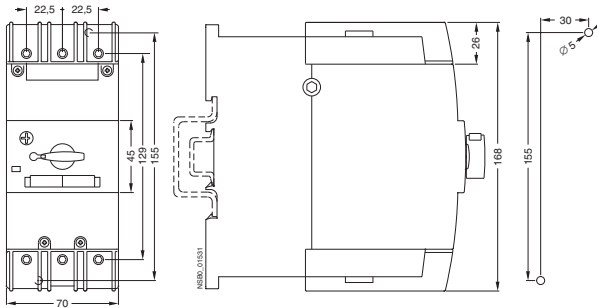

Circuit Diagrams

Internal connections

3RV17 Circuit Breaker

