


# Rock Solid Load Centers<sup>®</sup>

Main Lug Only, 1 $\emptyset$ , 65,000 AIC<sup>®</sup>, Main Lug Panels 3-Wire 120/240V AC or 208Y/120V AC, Insulated and Bonded Split Neutrals<sup>③</sup>

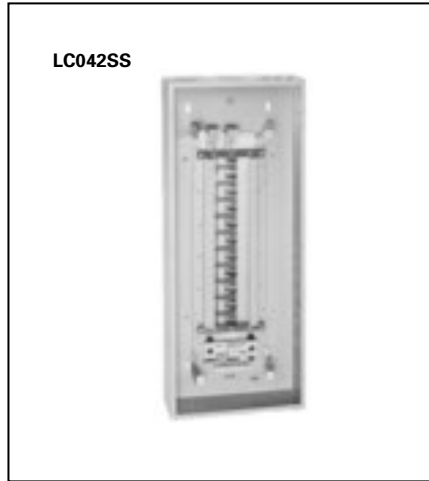

Load centers on this page through 225 amp feature a new split neutral with one bonded and one insulated bar. For service entrance applications, install bonding strap, and use both bars for neutral and ground conductors. For non service entrance applications, do not install bonding strap and use insulated bar for neutral conductors and bonded bar for ground conductors.

**NEW** White trim load centers are now available. Add a "W" to the end of any Rock Solid Load Center (100-225A). Must be ordered in pallet quantities (20-25) and a 3-4 week lead time applies.

## 12-42 Circuit, 125–400 Amperes

Amps Max.	No. of Spaces	Max. Circuit	Indoor Type 1 <sup>®</sup> Catalog Number	Dimensions <sup>®</sup>			List Price \$	Outdoor Type 3R <sup>®③</sup> Catalog Number	Dimensions <sup>®</sup>			List Price \$
				Height	Width	Depth			Height	Width	Depth	
125	12	24	LC1224L1125	21	14 $\frac{3}{8}$	4	255.00	LW1224L1125	20	14 $\frac{1}{4}$	4 $\frac{1}{2}$	408.00
125	16	32	LC1632L1125	21	14 $\frac{3}{8}$	4	334.00	LW1632L1125	29	14 $\frac{1}{4}$	4 $\frac{1}{2}$	491.00
125	20	40	LC2040L1125	24	14 $\frac{3}{8}$	4	423.00	LW2040L1125	29	14 $\frac{1}{4}$	4 $\frac{1}{2}$	572.00
125	30	40	LC3040L1125	30	14 $\frac{3}{8}$	4	533.00	—	—	—	—	—
150	16	32	LC1632L1150	24	14 $\frac{3}{8}$	4	417.00	—	—	—	—	—
150	24	40	LC2440L1150	30	14 $\frac{3}{8}$	4	505.00	—	—	—	—	—
200	12	24	—	—	—	—	—	LW1224L1200	29	14 $\frac{1}{4}$	4 $\frac{1}{2}$	555.00
200	20	40	LC2040L1200	30	14 $\frac{3}{8}$	4	593.00	LW2040L1200	29	14 $\frac{1}{4}$	4 $\frac{1}{2}$	737.00
200	24	40	LC2440L1200	30	14 $\frac{3}{8}$	4	602.00	—	—	—	—	—
200	30	40	LC3040L1200	36	14 $\frac{3}{8}$	4	644.00	LW3040L1200	38	14 $\frac{1}{4}$	4 $\frac{1}{2}$	834.00
200	40	40	LC4040L1200	39	14 $\frac{3}{8}$	4	880.00	—	—	—	—	—

## Copper Bus<sup>®</sup>

Amps Max.	No. of Spaces	Max. Circuit	Indoor Type 1 <sup>®</sup> Catalog Number	Dimensions <sup>®</sup>			List Price \$	Outdoor Type 3R <sup>®④</sup> Catalog Number	Dimensions <sup>®</sup>			List Price \$
				Height	Width	Depth			Height	Width	Depth	
125	20	40	LC2040L1125CU	24	14 $\frac{3}{8}$	4	449.00	—	—	—	—	—
200	20	40	LC2040L1200CU	30	14 $\frac{3}{8}$	4	627.00	—	—	—	—	—
200	30	40	LC3040L1200CU	36	14 $\frac{3}{8}$	4	682.00	—	—	—	—	—
200	40	40	LC4040L1200CU	39	14 $\frac{3}{8}$	4	933.00	—	—	—	—	—
225	12	24	—	—	—	—	—	LW1224L1225CU	29	14 $\frac{1}{4}$	4 $\frac{1}{2}$	728.00
225	42	42	LC4242L1225CU	42	14 $\frac{3}{8}$	4	990.00	LW4242L1225CU	42	14 $\frac{1}{4}$	4 $\frac{1}{2}$	1499.00
400	42	42	LC042SS <sup>®⑤</sup>	47	20	6	1925.00	LW042SR <sup>®</sup>	47	20 $\frac{1}{2}$	6 $\frac{1}{2}$	2499.00

## Value Pack<sup>®</sup>

Catalog Number	Load Center	Breakers	List Price \$
LC1224L1125P	LC1224L1125	(6) MP120	255.00

① Hub provision only. Closure plate included. Panels through 225A require HS type hub; panels over 225A require HV type hub. See accessories page 1-10, for hub selection.  
 ② If #2/0 feeder is used, order Cat #LX081M neutral lug kit.  
 ③ 300 & 400 Amp load centers have insulated groundable center-mounted neutrals.  
 ④ For flush installation, order accessory Cat #LX077SF separately.

⑤ Dimensions shown are representative of outside box length, width & depth ( $\pm \frac{1}{8}$ ") and do not include allowance for mounting bumps, endwalls, hubs or hardware protrusions. Allow approximately 1 $\frac{1}{2}$ " additional in length and width dimensions for surface or combination overhang. Consult factory for specific details if required.  
 ⑥ Standard package quantity equal to 1.  
 ⑦ Copper bus load centers are recommended for those applications where the environment may be severe (ie farm and coastal areas).

⑧ Convertible to main breaker by using the following main breaker kits:  
 100A load centers: MBK100M only.  
 125A load centers: MBK100M and MBK125M only.  
 150A load centers: MBK150M only.  
 200A load centers: MBK150M and MBK200M only.  
 225A load centers: MBK150M, MBK200M, and MBK225M only.  
 ⑨ Value packs include a load center and a mix of branch breakers.  
 ⑩ 100-225A only.