


Meter Sockets



SUAT111-0PQG



SUAT111-0G

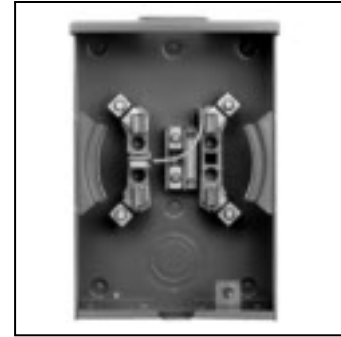

SUAT111-0MXA

135 Amp Continuous Meter Mounting Equipment— Ringless Type, 1 Phase, 3 Wire, 600V 1 Position Residential

Catalog Number	Replaces	Dimensions (inches)			Amps	Cont. Service	Wire Range	No. of Jaws	5th Jaw	Hub	KO Fig.	List Price \$
		H	W	D								
HORN BYPASS												
SUAT111-0PZA ^①	RJ192PX	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	RX Opening	1	99.05
SUAT111-0PQG	RJ193AX	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	RX Opening	1	95.85
SUAT111-0PV ^②	RJ193CXJ	11.7	8.0	3.6	135	OH/UG	#14-2/0	5	EC659-0121	RX Opening	1	93.00
SUAT111-BPQG	RJ192AC	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	1-1/2" Hub Installed	1	145.91
NO BYPASS												
SUAT111-BG	RJ103AC	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	1-1/2" Hub Installed	1	140.58
SUAT111-0MXA ^①	RJ102CXJ	11.7	8.0	3.6	135	OH/UG	#14-2/0	5	Installed	RX Opening	1	101.18
SUAT111-0G	RJ103AX	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	RX Opening	1	104.37
SUAT111-0GF ^③	RJ103AXF	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	RX Opening	1	92.66
SUAT111-PG	RN102A	11.7	8.0	3.6	135	UG	#14-2/0	4	EC659-0121	None	1	99.05

135 Amp Continuous Meter Mounting Equipment— Ring Type, 1 Phase, 3 Wire, 600V 1 Position Residential^④

Catalog Number	Dimensions (inches)			Amps	Cont. Service	Wire Range	No. of Jaws	5th Jaw	Hub	KO Fig.	List Price \$
	H	W	D								
NO BYPASS											
SN152CX	11.7	8.0	3.6	135	OH	#14-2/0	5	Installed	RX Opening	1	108.63
SN152CC	11.7	8.0	3.6	135	OH/UG	#14-2/0	5	Installed	1-1/2" Hub Installed	1	124.61
SJ102AX	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	RX Opening	1	90.53
SJ102AC	11.7	8.0	3.6	135	OH/UG	#14-2/0	4	EC659-0121	1-1/2" Hub Installed	1	91.59
SN102A	11.7	8.0	3.6	135	UG	#14-2/0	4	EC659-0121	None	1	99.05
SN152C	11.7	8.0	3.6	135	UG	#14-2/0	5	Installed	None	1	108.63

Contact utility or sales office for approval by your local utility prior to installation.


All devices listed on this page include (2) ground lugs

①7/16" Barrel lock knockout
 ②7/8" Barrel lock knockout
 ③Stainless steel latch and hasp
 ④Sealing ring included


Meter Sockets



SUAT417-XPQG

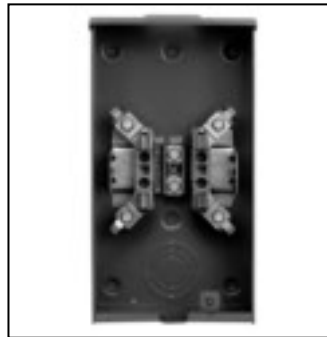

SUAT317-0PQG

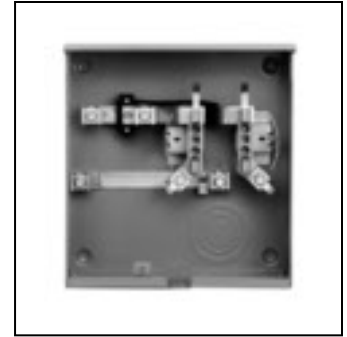

SUAS877-PPZ

200 Amp Continuous 250 Amp Max Meter Mounting Equipment Ringless Type, 1 Phase, 3 Wire, 600V 1 Position Residential

Catalog Number	Replaces	Dimensions (inches)			Amps	Cont. Service	Wire Range	No. of Jaws	5th Jaw	Hub	KO Fig.	List Price \$
		H	W	D								
HORN BYPASS												
SUAT317-0PQG	RS192AX	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	RX Opening	2	138.45
SUAT317-0FP ^②	RS192CXJ	14.8	8.0	4.5	200	OH	#6-350	5	Installed	RX Opening	2	203.42
SUAT317-0PGP ^②	RB193CXJ	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	RX Opening	2	203.42
SUAT317-0PZA ^①	RS192PX	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	RX Opening	2	138.45
SUAT417-XPQG	RB198AR	14.8	11.0	4.5	200	OH/UG	#6-350	4	EC659-0121	RX CL. Plate	3A	187.44
SUAT417-XPQG	RS192A	14.8	11.0	4.5	200	UG	#6-350	4	EC659-0121	RX CL. Plate	3B	264.12
SUAT417-XFP ^②	RS192COJ	14.8	11.0	4.5	200	UG	#6-350	5	Installed	RX CL. Plate	3B	203.42
SUAS877-PPZ	RL199A	14.0	13.0	5.1	200	UG-SW	#6-350	4	EC659-0121	None	6	264.12
SUAS877-PPZA ^①	RL199P	14.0	13.0	5.1	200	UG-SW	#6-350	4	EC659-0121	None	6	267.32
SUAS877-PPGP ^②	RL199CJ	14.0	13.0	5.1	200	UG-SW	#6-350	5	Installed	None	6	275.84
NO BYPASS												
SUAT317-DGZ	RS103AL	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	EC38599 Inst.	2	131.00
SUAT317-0GF ^③	RS103AXF	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	RX Opening	1	161.88
SUAT317-0G	RS103AX	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	RX Opening	1	146.97
SUAT317-0FP ^②	RB103CXJ	14.8	8.0	4.5	200	OH	#6-350	5	Installed	RX Opening	2	203.42
SUAT417-XGF ^③	RS109ARF	14.8	11.0	4.5	200	OH/UG	#6-350	4	EC659-0121	RX CL. Plate	3A	138.45
SUAT417-XG	RS109AR	14.8	11.0	4.5	200	OH/UG	#6-350	4	EC659-0121	RX CL. Plate	3A	192.77
SUAT618-XGNM ^{②④}	RB103CXJR	22.0	11.0	4.5	200	OH/UG	#6-350	4	EC659-0121	RX CL. Plate	5	320.57
SUAT417-XGDU	RB103AR	14.8	11.0	4.5	200	OH/UG	#6-350	4	EC659-0121	RX CL. Plate	3A	204.48
SUAT417-PG	RS103AVF	14.8	11.0	4.5	200	UG	#6-350	4	EC659-0121	None	3B	103.31
SUAT517-PDG ^①	RS109A	19.0	13.5	6.3	200	UG	#6-350	4	EC659-0121	None	4	166.14
SUAT417-PG	RS103A	14.8	11.0	4.5	200	UG	#6-350	4	EC659-0121	None	3B	103.31
SUAS877-PG ^①	RL109A	14.0	13.0	5.1	200	UG-SW	#6-350	4	EC659-0121	None	6	264.12

200 Amp Continuous 250 Amp Max Meter Mounting Equipment Ring Type, 1 Phase, 3 Wire, 600V 1 Position Residential

Catalog Number	Dimensions (inches)			Amps	Cont. Service	Wire Range	No. of Jaws	5th Jaw	Hub	KO Fig.	List Price \$
	H	W	D								
NO BYPASS											
SS152CX	14.8	8.0	4.5	200	OH	#6-350	5	Installed	RX Opening	2	140.58
SS102AX	14.8	8.0	4.5	200	OH	#6-350	4	EC659-0121	RX Opening	2	125.67
SS109AR	14.8	11.0	4.5	200	OH/UG	#6-350	4	EC659-0121	RX CL. Plate	3A	161.88
SS152C	14.8	11.0	4.5	200	UG	#6-350	5	Installed	None	3B	178.92

Contact utility or sales office for approval by your local utility prior to installation.

All SUAT type devices listed on this page include (2) ground lugs.

①7/16" Barrel lock knockout
 ②7/8" Barrel lock knockout
 ③Stainless steel latch and hasp
 ④Lugs not included please see accessory section for lug selection