


Meter Sockets


Ringless Type

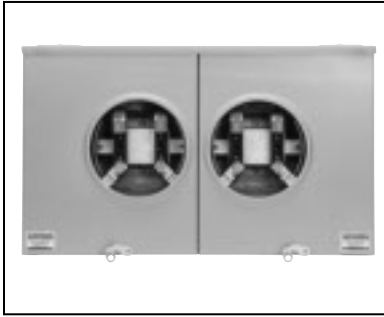

RN291PR



RN201CR

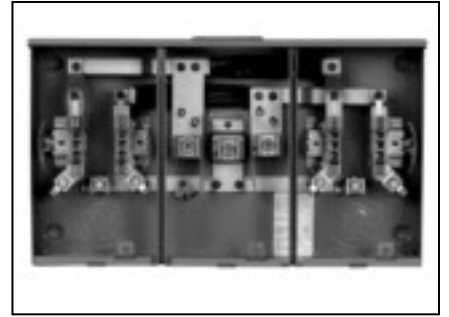

RM291PR

100 Amp/Position Meter Mounting Equipment 1 Phase, 3 Wire, 300V Multi-Position Residential End Feed

Catalog Number	Dimensions (inches)			Bus Amps	Cont. Amps	Service	No. of Pos.	No. of Jaws	5th Jaw	Hub	Line Lugs	Load Lugs	KO Fig.	List Price \$
	H	W	D											
HORN BYPASS														
RN291AR [Ⓞ]	14.1	24.3	5.3	200	100	OH/UG	2	4	EC659-0121	RX Opening	#6-250	#8-2/0	27	324.83
RN291PR [Ⓞ]	14.1	24.3	5.3	200	100	OH/UG	2	4	EC659-0121	RX Opening	#6-250	#8-2/0	27	324.83
RN391AR [Ⓞ]	14.1	32.3	5.3	200	100	OH/UG	3	4	EC659-0121	RX Opening	#6-250	#8-2/0	28	455.82
RN391PR [Ⓞ]	14.1	32.3	5.3	200	100	OH/UG	3	4	EC659-0121	RX Opening	#6-250	#8-2/0	28	455.82
RN491AR [Ⓞ]	14.1	40.5	5.3	200	100	OH/UG	4	4	EC659-0121	RX Opening	#6-250	#8-2/0	29	590.01
RN491PR [Ⓞ]	14.1	40.5	5.3	200	100	OH/UG	4	4	EC659-0121	RX Opening	#6-250	#8-2/0	29	590.01

NO BYPASS														
RN201CR	14.6	24.3	5.3	200	100	OH/UG	2	5	Installed	RX Opening	#6-250	#8-2/0	27	324.83
RN301CR	14.6	32.3	5.3	200	100	OH/UG	3	5	Installed	RX Opening	#6-250	#8-2/0	28	455.82
RN401CR	14.6	40.5	5.3	200	100	OH/UG	4	5	Installed	RX Opening	#6-250	#8-2/0	29	590.01

200 Amp/Position Meter Mounting Equipment 1 Phase, 3 Wire, 600V Multi-Position Residential Center Feed[Ⓞ]

Catalog Number	Dimensions (inches)			Bus Amps	Cont. Amps	Service	No. of Pos.	No. of Jaws	5th Jaw	Hub	Line Lugs	Load Lugs	KO Fig.	List Price \$
	H	W	D											
HORN BYPASS														
RM291PR	14.5	24.5	5.1	200	200	OH/UG	2	5	Installed	HD CL. Plate	#1/0-600	#6-350	19	337.61
RM391PR	14.5	33.3	5.1	270	200	OH/UG	3	5	Installed	HD CL. Plate	#1/0-600	#6-350	20	446.24
RM491PR	14.5	43.0	5.1	360	200	OH/UG	4	5	Installed	HD CL. Plate	#1/0-600	#6-350	21	605.99

[Ⓞ]7/16" Barrel lock knockout.
[Ⓞ]7/8" Barrel lock knockout.