


Meter Sockets


No Bypass & Lever Bypass Types

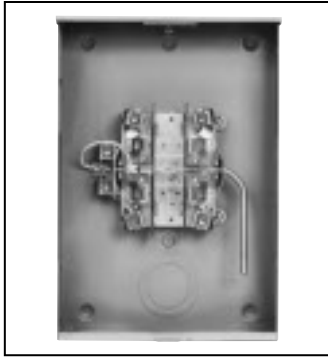

RH173CR



RH173GR

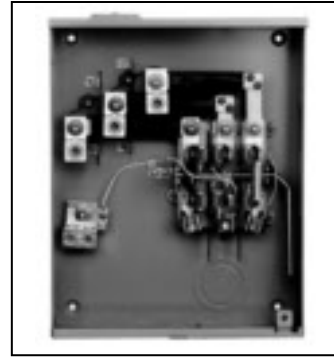

RL178GRJ

100 Continuous Amp Ring Type Meter Mounting Equipment No Bypass, 3 Phase, 4 Wire, 600V Commercial/Industrial^⑤

Catalog Number	Dimensions (inches)			Cont. Amps	Service	Wire Range	No. of Jaws	Hub Opening	KO Fig.	List Price \$
	H	W	D							
7 TERMINAL										
SE750CR	16.1	8.0	4.4	100	OH	#14-1/0	7	RX Opening	36	221.52

200 Continuous Amp Ringless Type Meter Mounting Equipment Lever Bypass, 1 Phase, 3 Wire or 3 Phase, 3 Wire, 600V Commercial/Industrial

(These units not rated for 3 Phase, 4 Wire Service)

Catalog Number	Replaces	Dimensions (inches)			Cont. Amps	Service	Wire Range	No. of Jaws	Hub Opening	KO Fig.	List Price \$
		H	W	D							
5 TERMINAL											
RH173CR ^②	—	19.0	13.0	5.1	200	OH/UG	#6-350	5	RX CL. Plate	9	459.02
RH173CRF ^{②③④}	—	19.0	13.0	5.1	200	OH/UG	#6-350	5	RX CL. Plate	9	463.28
RH173CRJ ^②	—	19.0	13.0	5.1	200	OH/UG	#6-350	5	RX CL. Plate	9	463.28
S42505-02RG ^{②④}	RH173CRR	19.0	13.0	5.1	200	OH/UG	3/8-24 Stud	5	RX CL. Plate	9	463.28
S40405-0BNU ^①	RH173CRJNU	28.0	13.0	5.1	200	OH/UG	#6-350	5	RX Opening	9	448.37
S48805-0BNU ^{①④}	RH178CRJNU	22.0	16.0	5.0	200	OH/UG	#6-350	5	RX CL. Plate	10	548.48

200 Continuous Amp Ringless Type Meter Mounting Equipment Lever Bypass, 3 Phase, 4 Wire, 600V Commercial/Industrial^④

Catalog Number	Replaces	Dimensions (inches)			Cont. Amps	Service	Wire Range	No. of Jaws	Hub Opening	KO Fig.	List Price \$
		H	W	D							
7 TERMINAL											
RH173GR ^②	—	19.0	13.0	5.2	200	OH/UG	#6-350	7	RX CL. Plate	9	581.49
RH173GRF ^{②③}	—	19.0	13.0	5.2	200	OH/UG	#6-350	7	RX CL. Plate	9	594.27
RH173GRJ ^②	—	19.0	13.0	5.1	200	OH/UG	#6-350	7	RX CL. Plate	9	594.27
S9804-9142 ^②	RL178GRJ	20.0	16.0	5.1	200	UG-SW	#6-350	7	RX CL. Plate	33	717.81
S40407-01NU ^①	RH173GRJNU	19.0	13.0	5.2	200	OH/UG	#6-350	7	RX Opening	9	532.50
S48807-02NU ^①	RH178GRJNU	22.0	16.0	5.0	200	OH/UG	#6-350	7	RX CL. Plate	10	630.48

Contact utility or sales office for approval by your local utility prior to installation.

①7/16" Barrel lock knockout
 ②7/8" Barrel lock knockout
 ③Stainless steel latch and hasp
 ④Ground lug included
 ⑤No bypass installed or available