

# Meter Sockets

## Ring Type & CT Metering



RTU121815



MS14TB



RP118SW

### Ring Type EUSERC-Approved Safety Sockets

Catalog Number	Replaces	Dimensions—Inches			Amps Cont. Duty	Service	Hub	No. of Jaws	5th Jaw	Wire Range Cu/Al	KO Fig.	List Price \$
		L	W	D								
MS14TB	BY110GK	24%	12%	4%	100	1 $\phi$ -3W	RX	4	UX005B	#6-2/0 Box Lug	39	578.00
MS15TB	BY110HK	24%	12%	4%		3 $\phi$ -3W	RX	5	INSTALLED		39	763.00
MS17TB	BY110JK	24%	12%	4%		3 $\phi$ -4W	RX	7	—		39	828.00
MS24TB	BY120GK	30%	14%	6%	200	1 $\phi$ -3W	RX	4	UX001WL	#1/0-250 kcmil Lay-in Lug	40	1078.00
MS25TB	BY120HK	30%	14%	6%		3 $\phi$ -3W	HC	5	INSTALLED		41	1266.00
MS27TB	BY120JK	30%	14%	6%		3 $\phi$ -4W	RX	7	—		40	1266.00


### 400 Ampere Transformer Rated CT-Meter Cabinet, (No Disconnect) 600V AC Max. ①②

Catalog Number	Replaced by	Dimensions (in inches)			No. of Jaws	Hub	KO Fig.	List Price \$
		L	W	D				
<b>1 Phase-3 Wire</b>								
RTU121814	—	52.00	24.00	11.00	4	—	42	1403.00
RTU121815	—	52.00	24.00	11.00	5	—	42	1415.00
<b>3 Phase-3 Wire</b>								
RTU121818	—	52.00	24.00	11.00	8	—	42	1419.00
<b>3 Phase-3 Wire or 3 Phase-4 Wire</b>								
RT121413	9837-8505	20.00	12.00	4.63	13	RX	43	749.76
RTU122015	—	52.00	36.00	11.00	15	—	42	2334.00

### CT Mounting Bases-400 Amp Max.

Catalog Number	Replaces	Service	Max. AIC	Wire Range	List Price \$
RT6019A	—	1 Phase/3 Phase-3 Wire	10,000	(2) NEMA Studs	379.00
RT6019HA	—	1 Phase- 3 Wire	50,000	(2) NEMA Studs	476.00
RT6067A	—	3 Phase- 4 Wire	10,000	(2) NEMA Studs	708.00
RT6067HA	—	3 Phase- 4 Wire	50,000	(2) NEMA Studs	830.00

Contact utility or sales office for approval by your local utility prior to installation.

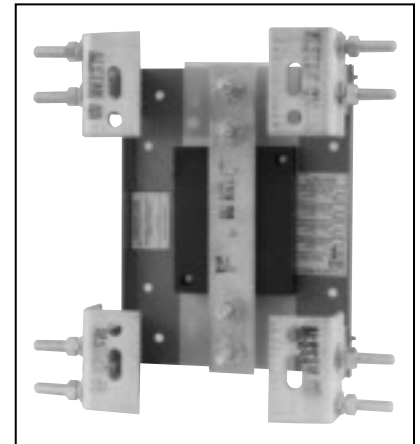

RT6019A

①CT mounting base not included, order from chart below  
 ②Includes Test Switch mounting provision, and hub opening for overhead feed