 



Meter Load Center Combinations

Over-Under Construction Meter Load Center Combinations, 150A-200A



- UL listed
- Overhead and underground feed applications
- Underground feed accomplished by use of removable gutter trough
- Load wires bottom or back exit only
- 22,000 AIC rated
- Pad locking provisions on all devices
- Side hinge doors removable by backing out only one screw
- Suitable for use only as service entrance equipment
- RX type hub provision on top end wall
- HC type hub provision on bottom end wall
- Field addable 5th Jaw (EC5J2)
- Contact local utility to confirm meter socket placement prior to installation
- See end of section for 5th jaw, main breaker, dimensions and wiring diagrams

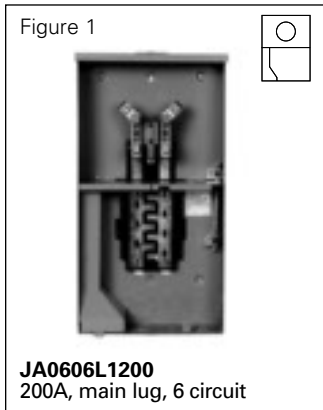

METER CENTERS 3

Combination Meter Sockets

Over-Under Combination Construction Meter Load Center Combinations												
Amps Max.	No. of Spaces	Max. Circuits	Cover Type	Mounting	Service	Bypass Type	Catalog Number	Dimensions			List Price \$	Figure
								Height	Width	Depth		
150	4	8	Ringless	Surface	OH/UG	—	JA0408B1150RT [Ⓢ]	30.0	13.9	4.9	1404.00	2
150	4	8	Ring	Surface	OH/UG	—	JA0408B1150T [Ⓢ]	30.0	13.9	4.9	1404.00	2
150	8	16	Ring	Surface	OH/UG	—	JA0816B1150CT [Ⓢ]	32.0	13.9	4.9	1477.00	3
150	8	16	Ringless	Surface	OH/UG	—	JA0816B1150RCT [Ⓢ]	32.0	13.9	4.9	1477.00	3
200	12	6	Ring	Surface	OH/UG	—	JA0606L1200 ^{ⓈⓈⓈ}	27.0	13.9	4.9	1099.00	1
200	12	6	Ringless	Surface	OH/UG	—	JA0606L1200R ^{ⓈⓈⓈ}	27.0	13.9	4.9	1099.00	1
200	12	6	Ringless	Surface	OH/UG	—	JA0606L1200RA ^{ⓈⓈⓈⓈ}	27.0	13.9	4.9	1331.00	1
200	4	8	Ringless	Surface	OH/UG	—	JA0408B1200RT [Ⓢ]	30.0	13.9	4.9	1404.00	2
200	4	8	Ring	Surface	OH/UG	—	JA0408B1200T [Ⓢ]	30.0	13.9	4.9	1404.00	2
200	8	16	Ring	Surface	OH/UG	—	JA0816B1200CT [Ⓢ]	32.0	13.9	4.9	1477.00	3
200	8	16	Ringless	Surface	OH/UG	—	JA0816B1200RCT [Ⓢ]	32.0	13.9	4.9	1477.00	3

Over-Under Construction Meter Load Center Combinations												
Amps Max.	No. of Spaces	Max. Circuits	Cover Type	Mounting	Service	Bypass Type	Catalog Number	Dimensions			List Price \$	Figure
								Height	Width	Depth		
200	8	16	Ringless	Surface	OH	—	JA0816B1200RT	28.9	12.5	4.9	1441.00	4
200	8	16	Ring	Surface	OH	—	JA0816B1200T	28.9	12.5	4.9	1391.00	4

Ⓢ No main breaker provided. Accept MD-T or MP-T type 2 or 4-pole breakers.
 Ⓢ Suitable for use as service entrance equipment when not more than six disconnecting means are provided and when not used as a lighting or appliance panel board.

Ⓢ Due to wire space restrictions on the trough side, the left side of the interior is limited to a 60A max branch.
 Ⓢ Aluminum enclosure.
 Ⓢ Suitable for use as service entrance equipment when not more than six disconnecting means are provided and when not used as a lighting and appliance panel branch circuit panel board.