
 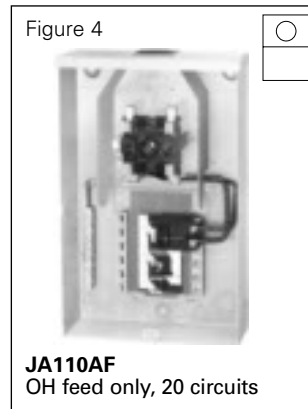


Meter Load Center Combinations

Meter Load Center Combinations, 100A-400A

- UL listed
- 22,000 AIC Rated
- Pad locking provisions on all devices
- Side hinge doors removable by backing out only one screw
- Suitable for use only as service entrance equipment
- Contact local utility to confirm meter socket approval prior to installation
- See end of section for 5th jaw, main breaker, dimensions and wiring diagrams



3
METER CENTERS

| Side-By-Side Construction Meter Load Center Combinations | | | | | | | | | | | | |
|--|---------------|---------------|------------|----------|---------|-------------|------------------------------|------------|-------|-------|---------------|--------|
| Amps Max. | No. of Spaces | Max. Circuits | Cover Type | Mounting | Service | Bypass Type | Catalog Number | Dimensions | | | List Price \$ | Figure |
| | | | | | | | | Height | Width | Depth | | |
| 150 | 8 | 16 | Ringless | Surface | OH/UG | — | JA0816B1150RTH [Ⓢ] | 21.0 | 22.8 | 5.0 | 1404.00 | 1 |
| 150 | 8 | 16 | Ring | Surface | OH/UG | — | JA0816B1150TH [Ⓢ] | 21.0 | 22.8 | 5.0 | 1404.00 | 1 |
| 200 | 8 | 16 | Ringless | Surface | OH/UG | — | JA0816B1200RTH [Ⓢ] | 21.0 | 22.8 | 5.0 | 1477.00 | 1 |
| 200 | 8 | 16 | Ring | Surface | OH/UG | — | JA0816B1200TH [Ⓢ] | 21.0 | 22.8 | 5.0 | 1477.00 | 1 |
| 200 | 20 | 40 | Ring | Surface | OH/UG | — | JA2040B1200 [Ⓢ] | 18.0 | 22.8 | 5.0 | 1099.00 | 1 |
| 350 | 8 | 16 | Ringless | Surface | OH/UG | Lever | JA0816B1350RLTM [Ⓢ] | 29.0 | 27.0 | 6.0 | 1099.00 | 2 |
| 400 | 4 | 8 | Ringless | Surface | OH/UG | Lever | JA0408B1400RLTM [Ⓢ] | 29.0 | 27.0 | 6.0 | 1331.00 | 2 |
| 400 | 8 | 16 | Ringless | Surface | OH/UG | Lever | JA0816B1400RLTM [Ⓢ] | 29.0 | 27.0 | 6.0 | 1404.00 | 2 |

| Side-By-Side 400A Construction Meter Load Center Combinations | | | | | | | | | | | | |
|---|---------------|---------------|------------|----------|---------|-------------|----------------|------------|-------|-------|---------------|--------|
| Amps Max. | No. of Spaces | Max. Circuits | Cover Type | Mounting | Service | Bypass Type | Catalog Number | Dimensions | | | List Price \$ | Figure |
| | | | | | | | | Height | Width | Depth | | |
| 400 | 30 | 42 | Ring | Surface | UG | Lever | JA3042B1400SDL | 39.6 | 30.1 | 6.3 | 5818.00 | 3 |

| Over-Under Construction Meter Load Center Combinations | | | | | | | | | | | | |
|--|---------------|---------------|------------|----------|---------|-------------|----------------------|------------|-------|-------|---------------|--------|
| Amps Max. | No. of Spaces | Max. Circuits | Cover Type | Mounting | Service | Bypass Type | Catalog Number | Dimensions | | | List Price \$ | Figure |
| | | | | | | | | Height | Width | Depth | | |
| 100 | 10 | 20 | Ring | Flush | OH | — | JA110AF [Ⓢ] | 19.3 | 12.1 | 4.3 | 688.00 | 4 |
| 100 | 10 | 20 | Ring | Flush | OH | — | JA110AS [Ⓢ] | 19.3 | 12.1 | 4.3 | 688.00 | 4 |
| 200 | 20 | 40 | Ring | Flush | OH | — | JA220CS [Ⓢ] | 30.5 | 14.3 | 4.3 | 1790.00 | 5 |
| 200 | 20 | 40 | Ring | Flush | OH | — | JA220CF [Ⓢ] | 30.5 | 14.3 | 4.3 | 1790.00 | 5 |

Ⓢ Feed thru lugs included.
 Ⓢ Side by side design for OH/UG applications.

Ⓢ Over/under design for OH applications.
 Ⓢ Not suitable for 5th jaw applications.

Ⓢ Semi-Flush mounting only.
 Ⓢ Closure plate included.

Combination
Meter Sockets