 


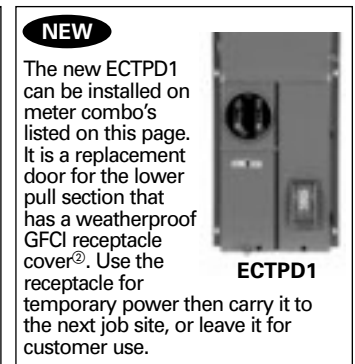
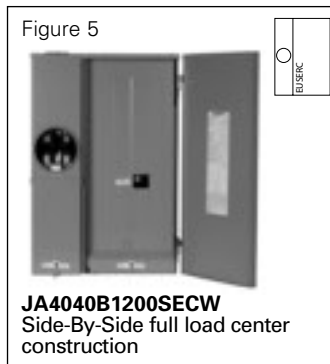
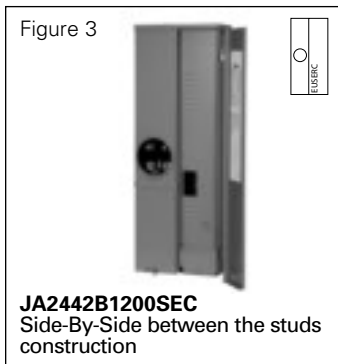


EUSERC Meter Load Center Combinations

EUSERC Meter Load Center Combinations, 100A-225A

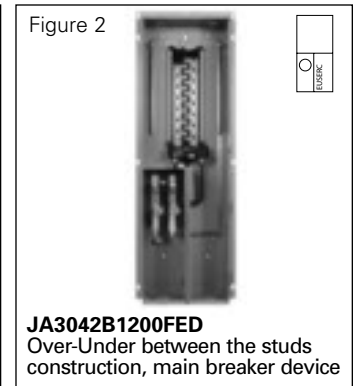

- UL listed
- For overhead and underground feed applications
- Designed to meet EUSERC standards
- 22,000 AIC Rated
- Pad locking provisions on all devices
- Surface and semi-flush units available - semi flush rails are depth adjustable for 2x6 studs
- Side hinge door removable by backing out only one screw
- Load wiring may exit top or bottom
- Suitable for use only as service entrance equipment
- RX type hub provision on top endwall, HC type hub provision on bottom endwall
- 5th jaw accessory available (ECMC5J)
- Ring type meter covers
- Contact local utility to confirm meter socket approval prior to installation
- See end of section for dimensions and wiring diagrams

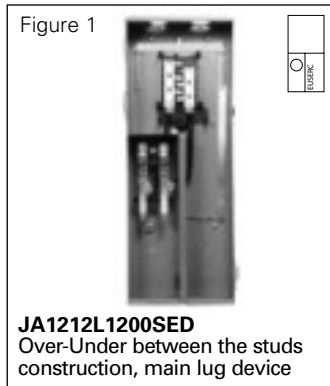

3 METER CENTERS

Over-Under Between the Studs Construction Meter Load Center Combinations										
Amps Max.	No. of Spaces	Max. Circuits	Mounting	Service	Catalog Number	Dimensions ^①			List Price \$	Figure
						Height	Width	Depth		
200	12	12	Flush	UG	JA1212L1200FED ^②	38-3/8	14-1/2	7-1/2	1424.00	1
200	12	12	Surface	UG	JA1212L1200SED ^②	38-3/8	14-1/2	7-1/2	1424.00	1
200	20	40	Surface	UG	JA2040B1200SED	41-7/8	14-1/2	7-1/2	2017.00	2
200	20	40	Flush	UG	JA2040B1200FED	41-7/8	14-1/2	7-1/2	2017.00	2
200	30	42	Surface	UG	JA3042B1200SED	48-3/8	14-1/2	7-1/2	2017.00	2
200	30	42	Flush	UG	JA3042B1200FED	48-3/8	14-1/2	7-1/2	2017.00	2
225	30	42	Surface	UG	JA3042B1225SED	48-3/8	14-1/2	7-1/2	2157.00	2
225	30	42	Flush	UG	JA3042B1225FED	48-3/8	14-1/2	7-1/2	2157.00	2

Side-By-Side Between the Studs Construction Meter Load Center Combinations										
Amps Max.	No. of Spaces	Max. Circuits	Mounting	Service	Catalog Number	Dimensions			List Price \$	Figure
						Height	Width	Depth		
100	12	24	Flush	OH/UG	JA1224B1100FEC	26-9/16	14-1/2	7-1/2	776.00	3
100	12	24	Surface	OH/UG	JA1224B1100SEC	26-9/16	14-1/2	7-1/2	776.00	3
100	16	32	Flush	OH/UG	JA1632B1100FEC	30-9/16	14-1/2	7-1/2	871.00	3
100	16	32	Surface	OH/UG	JA1632B1100SEC	30-9/16	14-1/2	7-1/2	871.00	3
125	12	24	Flush	OH/UG	JA1224B1125FEC	26-9/16	14-1/2	7-1/2	1049.00	3
125	12	24	Surface	OH/UG	JA1224B1125SEC	26-9/16	14-1/2	7-1/2	1049.00	3
125	16	32	Flush	OH/UG	JA1632B1125FEC	30-9/16	14-1/2	7-1/2	1787.00	3
200	24	42	Flush	OH/UG	JA2442B1200FEC	40-9/16	14-1/2	7-1/2	2099.00	3
200	24	48	Surface	OH/UG	JA2442B1200SEC	40-9/16	14-1/2	7-1/2	2099.00	3
200	8	16	Surface	OH/UG	JA0816B1200SCTM	40-9/16	14-1/2	7-1/2	1822.00	4

Side-By-Side Full Load Center Construction Meter Load Center Combinations										
Amps Max.	No. of Spaces	Max. Circuits	Mounting	Service	Catalog Number	Dimensions			List Price \$	Figure
						Height	Width	Depth		
200	30	40	Surface	OH/UG	JA3040B1200SECW ^③	32-1/4	21	5-1/8	776.00	5
200	30	40	Surface	OH/UG	JA4040B1200SECW ^③	32-1/4	21	5-1/8	776.00	5

① Suitable for use as service entrance equipment when not more than six main disconnecting means are provided and when not used as a lighting and appliance panel board.

② Consists of a door, hinges, and weatherproof cover. GFCI receptacle not included.

③ FRK1 - Flush rail kit.

Combination Meter Sockets