


# Combination Meter Sockets

## Electriccenter Accessories

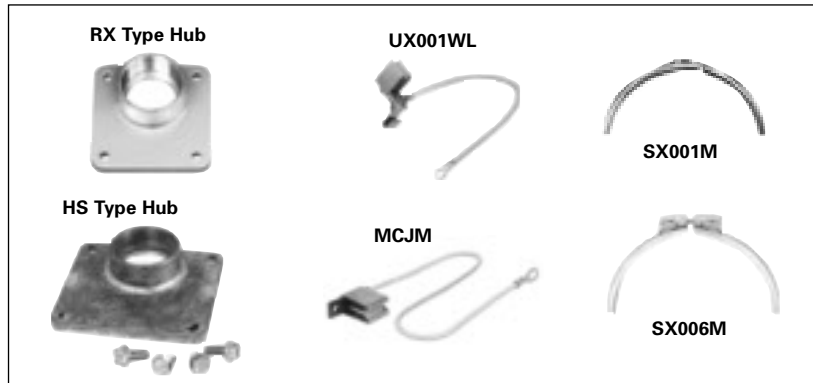

### Interchangeable Hubs

Conduit Size (Inches) Lbs.	Catalog Number	List Each
<b>HS Type Hubs</b>		
¾	ECHS075	42.00
1	ECHS100	42.00
1¼	ECHS125	42.00
1½	ECHS150	42.00
2	ECHS200	73.00
2½	ECHS250	116.00
<b>RX Type Hubs</b>		
¾	EC38594	22.90
1	EC38596	37.81
1¼	EC38597	37.81
1½	EC38598	23.96
2	EC38599	23.96
2½	EC38600	107.57
<b>HV Type Hubs</b>		
2	ECHV200	97.00
2½	ECHV250	133.00
3	ECHV300	193.00
3½	ECHV350	291.00
4	ECHV400	385.00
<b>HC Type Hubs</b>		
2	ECHC200	77.00
2½	ECHC250	115.00
3	ECHC300	186.00
<b>Accessories and Closure Plates</b>		
Adapter Plate	ECHCRXA	22.50
Closure Plates	ECHC000	25.50
	ECHS000	40.50
	ECHV000	25.00
	EC38595	38.34

### Grounding Bars (Al/Cu — except where noted)

Grounding bars are for use where grounding of electrical outlets and devices is by means of conductors. Each bar is equipped with large connectors rated for one #14-1/0 or, two or three #14-10 Cu/Al and small connectors rated for one #14-6 or, two #14-12 Cu/Al. (May be restricted by wire bending space.)

Length	Number of Connectors			Catalog Number	List Each
	Total	Large	Small		
1½	4	0	4	ECLX068M	12.50
2¾	7	2	5	ECLX069M	16.60
3½	11	3	8	ECLX071M	16.60
4¾	15	4	11	ECLX072M	18.80
5¾	19	5	14	ECLX073M	19.80
7	23	6	17	ECLX074M	27.00
8¾	27	7	20	ECLX075M	30.50

### Sealing Rings

Description	Catalog Number	List Each
Snap-on type, aluminum	SRSTD	17.47
Screw type, aluminum	SRSW	25.03

### Miscellaneous Accessories

Description	Catalog Number	List Each
Plastic Meter Opening Cover (JA, JC)	ECPP	20.00
Plastic Meter Cover Ringless (JB)	ECCP3	22.50
Fifth Jaw (for old style JA & JC units only)	UX001WL	25.00
NEMA Stud Mechanical Lugs for JB, JK and JL units <sup>①</sup> (2) #6-350 kcmil (1) #2-600 kcmil Al/Cu (2) #500-1000 kcmil Al/Cu	UK350TA	59.00
	UK600TA	53.00
	UK1000TA	68.00
5th jaw for new style JA & JC devices	EMC5J	77.00
Neutral Feeder Lugs #2-1/0 #4-2/0 #1-350 kcmil	ECLK1	9.30
	ECLK2	19.60
	ECLK3	25.50

① Order one for each phase and neutral.

② No main breaker provided. Accept MD-T or MP-T type 2 or 4-pole breakers.

Catalog Number	Main Breaker	5th Jaw
JC002CS	MP-T	—
JC002CZ	MP-T	—
JC002AR	MP-T	—
JC0406L1200H	(1) MD-T, MD-HT or (2) MP-T, MP-HT	ECMC5J
JC0406L1200RH		ECMC5J
JC0406L1200RHJB		Included
JC0404L1400RLM	(2) MD-T(R), MD-HT(R), MP-T, MP-HT	S35815-2
JC0202B1125RJB	MP2125KH	Included
JC0202B1200	MPD2200KH	ECMC5J
JC0202B1200R	MPD2200KH	ECMC5J
JC0202B1200RJB	MPD2200KH	Included
JA0408B1150T	ME9683	EC5J2
JA0408B1150RT	ME9683	EC5J2
JA0816B1150CT	ME9683	EC5J2
JA0816B1150RCT	ME9683	EC5J2
JA0606L1200	⊙	EC5J2
JA0606L1200R	⊙	EC5J2
JA0606L1200RA	ME9683	EC5J2
JA0408B1200T	ME9683	EC5J2
JA0408B1200RT	ME9683	EC5J2
JA0816B1200CT	ME9683	EC5J2
JA0816B1200RCT	ME9683	EC5J2
JC002CS	MP-T	—
JC002CZ	MP-T	—
JC002AR	MP-T	—
JC0406L1200H	(1) MD-T, MD-HT or (2) MP-T, MP-HT	ECMC5J
JC0406L1200RH		ECMC5J
JC0406L1200RHJB		Included
JC0404L1400RLM	(2) MD-T(R), MD-HT(R), MP-T, MP-HT	RX815FJ
JA1212L1200FED	NA	ECMC5J
JA1212L1200SED	NA	ECMC5J
JA2040B1200FED	MBK200M	ECMC5J
JA2040B1200SED	MBK200M	ECMC5J
JA3042B1200FED	MBK200M	ECMC5J
JA3042B1200SED	MBK200M	ECMC5J
JA3042B1225FED	MBK225M	ECMC5J
JA3042B1225SED	MBK225M	ECMC5J
JA1224B1100FEC	MP2100KH	ECMC5J
JA1224B1100SEC	MP2100KH	ECMC5J
JA1632B1100FEC	MP2100KH	ECMC5J
JA1632B1100SEC	MP2100KH	ECMC5J
JA1224B1125FEC	MP2125KH	ECMC5J
JA1224B1125SEC	MP2125KH	ECMC5J
JA1632B1125FEC	MP2125KH	ECMC5J
JC0406L1125FEC	MP2125KH	ECMC5J
JC0406L1125SEC	MP2125KH	ECMC5J
JA2442B1200FEC	MEQ9985	ECMC5J
JA2442B1200SEC	MEQ9985	ECMC5J
JC0406L1200FEC	MEQ9985	ECMC5J
JC0406L1200SEC	MEQ9985	ECMC5J
JA3040B1200SECW	MPD2200RH	ECMC5J
JA4040B1200SECW	MPD2200RH	ECMC5J