



Meter Centers

Uni-Pak Metering: Selection-Ring Style

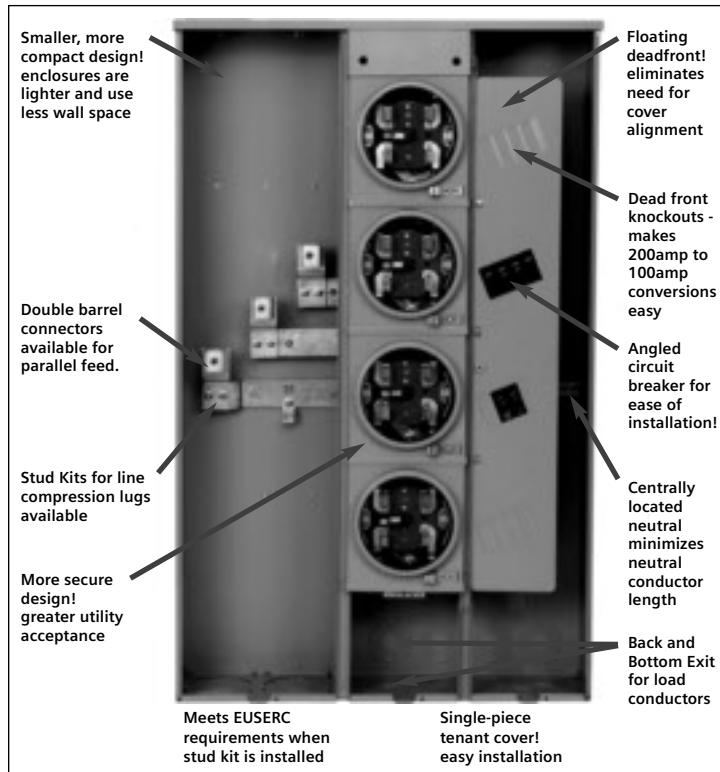

Features

- Individual split covers
- UL Listed for 60 / 75°C conductors. See equipment markings for applications
- For small apartment buildings, small professional and commercial buildings
- Completely self-contained meter centers
- Two to six 125A and 200A sockets breaker positions
- Outdoor surface mounted enclosures
- Compact, pre-bussed, easy to handle, hang and wire
- Barriered, sealable compartment for un-metered current-carrying parts
- Al/Cu lay-in lugs, except two socket units
- Top or bottom feed
- Bottom and rear branch wiring exits (Neutral and ground at bottom only)
- ANSI #61 light gray electrodeposited paint on zinc-coated G90 steel
- Meets EUSERC specifications when NEMA stud kit and flushing ring (if required) is field added

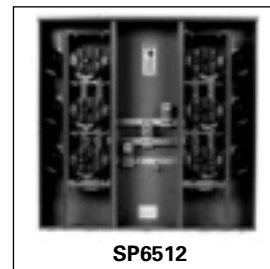

1-Phase, 3-Wire SN, Ring Type, Uni-Pak Meter Center

Continuous Duty Amps Per Position	Bus Amperage	Meter Positions Per Pak	Catalog Number	Old Catalog Number	Breaker Provision	Maximum AIC	Dimensions ^①			5th Jaw Assembly	Line Lugs Wire Range	List Price \$
							Height	Width	Depth			

1-Phase, 4-Jaw Sockets, 120/240V AC Max.

125	200	2	SP2211	MP2211	MP-T MP-HT MP-MT	65,000	37.63	13.67	6.00	ECMM5J	#6-300 kcmil	1323.00
	300	3	SP3311	MP3311		65,000	38.40	25.50	7.50	ECMM5J	#6-300 kcmil	1591.00
	400	4	SP4411	MP4411		65,000	47.40	25.50	7.50	ECMM5J	1/0-750 MCM CU-AL or (2) 1/0-250 AL or (2) 1/0-3/0 CU	2260.00
	400	5	SP4511	MP4511		65,000	38.40	39.20	7.50	ECMM5J		2861.00
	400	6	SP4611	MP4611		65,000	38.40	39.20	7.50	ECMM5J	(2) #2-600 kcmil	3315.00
	500	4	SP5411	MP5411		65,000	47.40	31.50	7.50	ECMM5J		2807.00
	600	5	SP6511	MP6511		65,000	38.40	45.20	7.50	ECMM5J	3235.00	
	600	6	SP6611	MP6611		65,000	38.40	45.20	7.50	ECMM5J	3877.00	
200	400	2	SP4212	MP4212	MP-T MP-HT MP-MT MPP-T MPP-HT MPP-MT MPP-PT	100,000	31.50	29.50	7.50	ECMM5J	1/0-750 MCM CU-AL or (2) 1/0-250 AL or (2) 1/0-3/0 CU	1863.00
	400	3	SP4312	MP4312		100,000	38.44	29.50	7.50	ECMM5J		2755.00
	400	4	SP4412	MP4412		100,000	47.44	29.50	7.50	ECMM5J	3612.00	
	600	4	SP6412	MP6412		100,000	47.44	35.50	7.50	ECMM5J	3983.00	
	600	5	SP6512	MP6512		100,000	38.44	53.10	7.50	ECMM5J	(2) #2-600 kcmil	4655.00
	600	6	SP6612	MP6612		100,000	38.44	53.10	7.50	ECMM5J		5460.00
	800	6	SP8612 ^②	—		100,000	38.44	53.10	7.50	ECMM5J		5991.00

Flushing Rail Kits:	Description	List Price \$
---------------------	-------------	---------------

125 Amps per position

SP221FK	2 Gang 200 amp bus	132.00
SP331FK	3 Gang 300 amp bus	154.00
SP441FK	4 Gang 400 amp bus	154.00
SP4561FK	5&6 Gang 400 amp bus	154.00
SP6561FK	5&6 Gang 600 amp bus	154.00

200 Amps per position

SP422FK	2 Gang 400 amp bus	154.00
SP432FK	3 Gang 400 amp bus	154.00
SP442FK	4 Gang 400 amp bus	154.00
SP642FK	4 Gang 600 amp bus	154.00
SP6562FK	5&6 Gang 600 amp bus	154.00

① Dimensions shown are representative of outside box length, width, & depth and do not include allowances for mounting bumps, endwalls, covers, hubs or hardware protrusions.

② Order NSK600 stud kit for use with 800A device. Copper cable only.