


Meter Centers

Uni-Pak Metering: Selection-Ringless Style^③

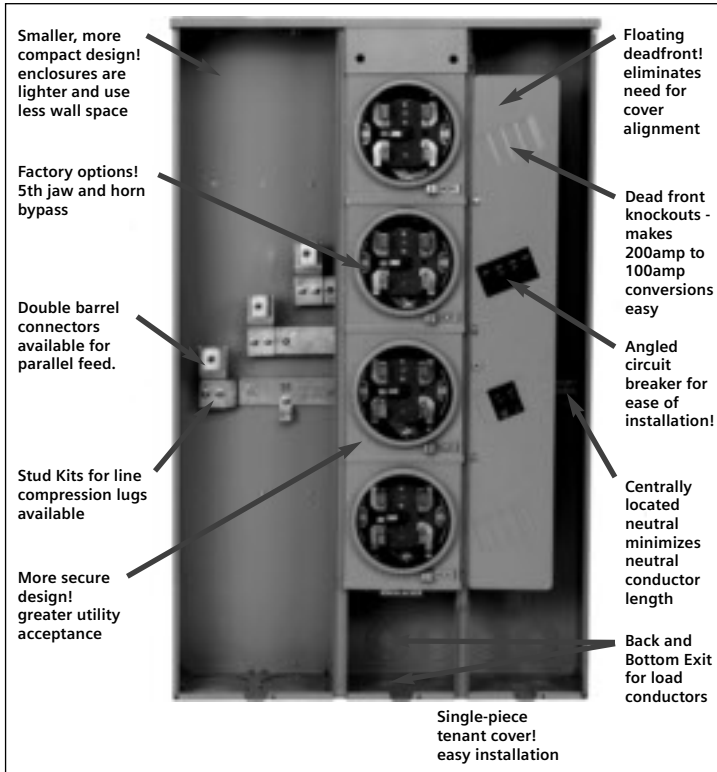

Features

- Ringless meter construction
- Individual split covers with barrel lock compatibility
- Available with horn bypass factory installed
- UL Listed for 60/75°C conductors See equipment markings for applications
- For small apartment buildings, small professional and commercial buildings
- Completely self-contained meter centers
- Two to six 125A and 200A sockets breaker positions
- Compact, pre-bussed, easy to handle, hang and wire
- Barriered, sealable compartment for unmetered current-carrying parts
- Al/Cu lay-in lugs, except two socket units
- Top or bottom feed
- Bottom and rear branch wiring exits (Neutral and ground at bottom only)
- ANSI #61 light grey electrodeposited paint on zinc-coated steel
- 5th jaw kit included with each unit



1-Phase, 3-Wire SN, Ringless Type, Uni-Pak Meter Center - No Bypass & Horn Bypass

Continuous Duty Amps Per Position	Bus Amperage	Meter Positions Per Pak	Catalog Number	Old Catalog Number	Breaker Provision	Maximum AIC	Dimensions ^①			5th Jaw Assembly ^②	Horn Bypass Kit	Line Lugs Wire Range	List Price \$
							Height	Width	Depth				

1-Phase, 5-Jaw Sockets, 120/240V AC Max.

125	200	2	SP2211RJ	MP2211RJ	MP-T MP-HT MP-MT	65,000	37.50	13.50	6.00	Included	ECHBK	#6-300 kcmil	1429.00	
	200	2	SP2211RJB	MP2211RJB		65,000	37.50	13.50	6.00	Included	Installed		#6-300 kcmil	1428.00
	300	3	SP3311RJ	MP3311RJ		65,000	37.50	25.50	7.50	Included	ECHBK		#2-600 kcmil	1782.00
	300	3	SP3311RJB	MP3311RJB		65,000	37.50	25.50	7.50	Included	Installed		#2-600 kcmil	1701.00
	400	4	SP4411RJ	MP4411RJ		65,000	37.50	25.50	7.50	Included	ECHBK			2501.00
	400	4	SP4411RJB	MP4411RJB		65,000	37.50	25.50	7.50	Included	Installed			2501.00
	400	5	SP4511RJ	MP4511RJ		65,000	37.50	39.20	7.50	Included	ECHBK		1/0-750 MCM CU-AL or (2) 1/0-250 AL or (2) 1/0-3/0 CU	3129.00
	400	5	SP4511RJB	MP4511RJB		65,000	37.50	39.20	7.50	Included	Installed			3129.00
	400	6	SP4611RJ	MP4611RJ		65,000	37.50	39.20	7.50	Included	ECHBK			3666.00
	400	6	SP4611RJB	MP4611RJB		65,000	37.50	39.20	7.50	Included	Installed			3506.00
	600	5	SP6511RJ	MP6511RJ		65,000	37.50	45.20	7.50	Included	ECHBK			3557.00
	600	5	SP6511RJB	MP6511RJB		65,000	37.50	45.20	7.50	Included	Installed		(2) #2-600 kcmil	3557.00
	600	6	SP6611RJ	MP6611RJ		65,000	37.50	45.20	7.50	Included	ECHBK			4204.00
	600	6	SP6611RJB	MP6611RJB		65,000	37.50	45.20	7.50	Included	Installed			4040.00
200	400	2	SP4212RJ	MP4212RJ	MP-T MP-HT MP-MT MPP-T MPP-HT MPP-MT MPP-PT ^②	100,000	31.50	29.50	7.50	Included	ECHBK			1997.00
	400	2	SP4212RJB	MP4212RJB		100,000	31.50	29.50	7.50	Included	Installed			1940.00
	400	3	SP4312RJ	MP4312RJ		100,000	38.44	29.50	7.50	Included	ECHBK		1/0-750 MCM CU-AL or (2) 1/0-250 AL or (2) 1/0-3/0 CU	2943.00
	400	3	SP4312RJB	MP4312RJB		100,000	38.44	29.50	7.50	Included	Installed			2861.00
	400	4	SP4412RJ	MP4412RJ		100,000	47.44	29.50	7.50	Included	ECHBK			3822.00
	400	4	SP4412RJB	MP4412RJB		100,000	47.44	29.50	7.50	Included	Installed			3692.00
	600	5	SP6512RJ	MP6512RJ		100,000	38.44	53.10	7.50	Included	ECHBK			4789.00
	600	5	SP6512RJB	MP6512RJB		100,000	38.44	53.10	7.50	Included	Installed			4655.00
	600	6	SP6612RJ	MP6612RJ		100,000	38.44	53.10	7.50	Included	ECHBK		(2) #2-600 kcmil	5645.00
	600	6	SP6612RJB	MP6612RJB		100,000	38.44	53.10	7.50	Included	Installed			5458.00
	800	6	SP8612RJ ^③	—		100,000	38.44	53.10	7.50	Included	ECHBK			5991.00

① Dimensions shown are representative of outside box length, width, & depth and do not include allowances for mounting bumps, endwalls, covers, hubs or hardware protrusions.

② Order ECMI5J for insulated 5th jaw. Fifth terminal for RJ devices is included, but not installed.

③ Order NSK600 stud kit for use with 800A device. Copper Cable only.