



Meter Centers

Modular Metering: Residential Modules—Ring Style

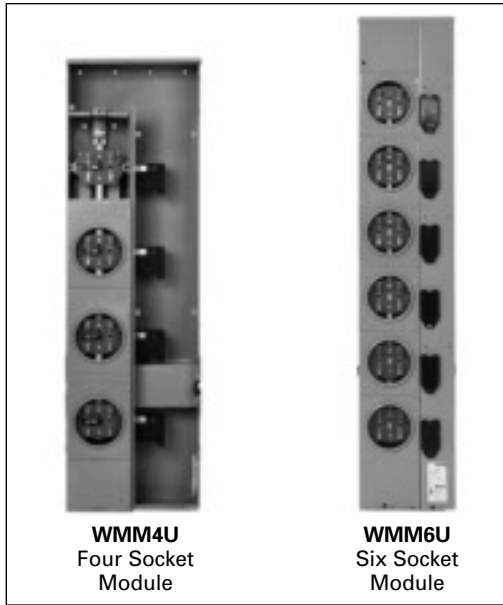

Features

- UL Listed for 60/75° C conductors. See equipment markings for applications
- 1200 Amp thru bus
- Factory phased 3ø units saves on installation time
- 200A units UL Listed for use on systems capable of delivering up to 100,000 RMS symmetrical amperes maximum short circuit current
- Single bolt joint coupler included. Order additional couplers as needed. Use closure plates from main device to seal openings on side for thru bus.

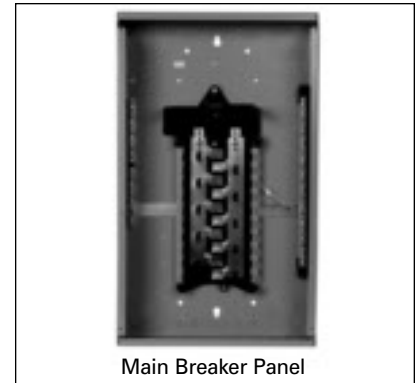

Main Breaker Panel

Series Tested Systems—Specify Siemens Modular Metering equipment in conjunction with Rock Solid Load Centers.

Check local utility requirements prior to installation.

1-Phase, 3-Wire SN, Incoming & Outgoing, Ring Type Gangable Meter Stack

Continuous Duty Amps Per Position	Meter Positions Per Stack	Catalog Number	Old Catalog Number	List Price \$	Breaker Provision	Maximum AIC ^③	Dimensions ^①			Field Installed 5th Jaw Assembly ^②	KO Fig.
							Height	Width	Depth		
1-Phase 4-Jaw Sockets, 1 Phase-3 Wire Thru-Bus 120/240V AC Max.											
125	2	WMM2U	—	1509.00	MP-T, MP-HT, MP-MT	65,000	32.41	13.44	7.84	ECMM5J	A12
	3	WMM3U	DG331W	1690.00		65,000	41.41	13.44	7.84	ECMM5J	A12
	4	WMM4U	DG431W	2218.00		65,000	50.41	13.44	7.84	ECMM5J	A13
	5	WMM5U	DG531W	2858.00		65,000	59.41	13.44	7.84	ECMM5J	A14
	6	WMM6U	DG631W	3516.00		65,000	68.41	13.44	7.84	ECMM5J	A15
200	2	WMM2200U	DG232W	3362.00	MPP-T, MPP-H, MPP-MT, MPP-PT, MP-T, MP-HT, MP-MT ^②	100,000	36.41	17.44	7.84	ECMM5J	A16
	3	WMM3200U	DG332W	3599.00		100,000	47.41	17.44	7.84	ECMM5J	A17
	4	WMM4200U	DG432W	4960.00		100,000	58.41	17.44	7.84	ECMM5J	A18

3-Phase, 4-Wire SN, Incoming and 1-Phase, 3-Wire SN Outgoing, Ring Type Gangable Meter Stacks

Continuous Duty Amps Per Position	Meter Positions Per Stack	Catalog Number	Old Catalog Number	List Price \$	Breaker Provision	Maximum AIC ^③	Dimensions ^①			5th Jaw Assembly	Stack Phasing: Phases/Socket	KO Fig.
							Height	Width	Depth			
1-Phase 5-Jaw Sockets, 3 Phase-4 Wire Thru-Bus 208Y/120V AC^③												
125	3	WMM34U	DG341W	1798.00	MP-T, MP-HT, MP-MT	65,000	41.41	13.44	7.84	Installed	1-AB, 1-BC, 1-CA	A12
	4	WMM44ABU	DG441W	2401.00		65,000	50.41	13.44	7.84	Installed	2-AB, 1-BC, 1-CA	A13
	4	WMM44BCU	—	2401.00		65,000	50.41	13.44	7.84	Installed	2-BC, 1-AC, 1-AB	A13
	4	WMM44CAU	—	2401.00		65,000	50.41	13.44	7.84	Installed	2-AB, 1-BC, 1-CA	A13
	5	WMM54ABU	DG541W	3097.00		65,000	59.41	13.44	7.84	Installed	1-AB, 2-BC, 2-CA	A14
	6	WMM64U	DG641W	3806.00		65,000	68.41	13.44	7.84	Installed	2-AB, 2-BC, 2-CA	A15
200	2	WMM24AB200U	DG242W	3417.00	MPP-T, MPP-H, MPP-MT, MPP-PT, MP-T, MP-HT, MP-MT ^②	100,000	36.41	17.44	7.84	Installed	1-BC, 1-CA	A16
	3	WMM34200U	DG342W	3806.00		100,000	47.41	17.44	7.84	Installed	1-AB, 1-BC, 1-CA	A17
	4	WMM44AB200U	DG442W	4852.00		100,000	58.41	17.44	7.84	Installed	2-AB, 1-BC, 1-CA	A18
	4	WMM44BC200U	—	4852.00		100,000	58.41	17.44	7.84	Installed	2-BC, 1-AC, 1-AB	A18
	4	WMM44CA200U	—	4852.00		100,000	58.41	17.44	7.84	Installed	2-AB, 1-BC, 1-CA	A18
	5	WMM54AB200U	—	5660.00		100,000	69.41	17.44	7.84	Installed	2-AC, 2-BC, 1-AB	A19
	5	WMM54BC200U	—	5660.00		100,000	69.41	17.44	7.84	Installed	2-AC, 2-AB, 1-BC	A19
	6	WMM54CA200U	—	5660.00		100,000	69.41	17.44	7.84	Installed	2-AB, 2-BC, 1-AC	A19

① Dimensions shown are representative of outside box length, width, & depth and do not include allowances for mounting bumps, endwalls, covers, hubs or hardware protrusions.

② Order filler plate ECCP3U if using standard 2" wide circuit breaker (QP/MP-T).
 ③ NOT for use on 3 phase-4 wire delta systems.
 ④ Order ECMM5J for insulated 5th jaw.

⑤ Max. AIC determined by maximum AIC of tenant breakers. Higher ratings may be achieved thru approved series rating combinations.