


Meter Centers

Commercial Meter Modules: Three Phase with Lever Bypass

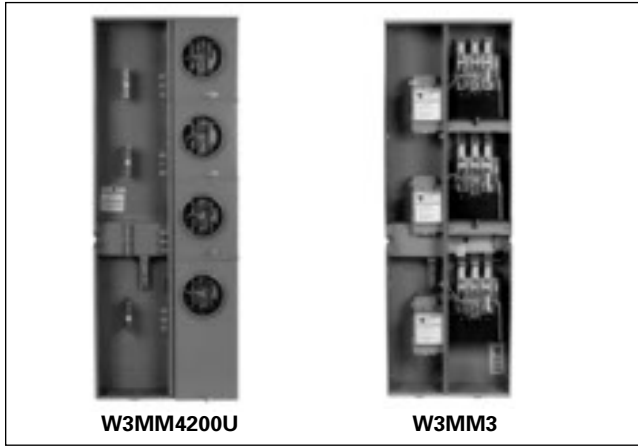

Features

- High-quality Landis & Gyr HQ lever bypass block
- Ground lugs mounted by each position
- Centrally located neutral lugs
- Horizontal breaker mounting reduces install time and effort
- 100amp modules save on tenant main cost



Features

- High-quality Landis & Gyr HQ lever bypass block
- 400amp tenant main breaker factory installed
- One & Two position units now available
- 42,000 AIC Rating

3
METERING

3-Phase, 4-Wire SN, Incoming and Outgoing, Ringless Type Lever Bypass Gangable Meter Stacks

| Thru-Bus Rating (amps) | Max Tenant Breaker (amps) | Meter Positions Per Stack | Catalog Number | Old Catalog Number | List Price \$ | Breaker Provision | Maximum AIC ^② | Dimensions ^① | | | Bypass Type | KO Fig. |
|---|---------------------------|---------------------------|-----------------------|--------------------|---------------|--------------------------------------|--------------------------|-------------------------|-------|-------|-------------|---------|
| | | | | | | | | Height | Width | Depth | | |
| 3-Phase 7-Jaw Sockets, 3 Phase-4 Wire Thru-Bus 208Y/120V AC Max. -Lever Bypass^② | | | | | | | | | | | | |
| 1200 | 100 | 1 | W3MM1 | DL141W7 | 3570.00 | MP-T, MP-HT, MP-MT ^③ | 65,000 | 29.11 | 20.21 | 8.93 | Lever | A31 |
| | | 2 | W3MM2 | DL241W7 | 6981.00 | | 65,000 | 44.70 | 20.21 | 8.93 | Lever | A32 |
| | | 3 | W3MM3 | DL341W7 | 10310.00 | | 65,000 | 61.20 | 20.21 | 8.93 | Lever | A33 |
| | | 4 | W3MM4 | DL441W7 | 13783.00 | | 65,000 | 77.70 | 20.21 | 8.93 | Lever | A34 |
| 3-Phase 7-Jaw Sockets, 3 Phase-4 Wire Thru-Bus 240V AC Max. -Lever Bypass | | | | | | | | | | | | |
| 1200 | 200 | 1 | W3MM1200U | DL142W7 | 3570.00 | QJ, QH2, QJ2-H, HQJ2-H, MQ, MQH, MQL | 100,000 | 23.75 | 23.50 | 9.13 | Lever | A20 |
| | | 2 | W3MM2200U | DL242W7 | 6981.00 | | 100,000 | 36.75 | 23.50 | 9.13 | Lever | A21 |
| | | 3 | W3MM3200U | DL342W7 | 10310.00 | | 100,000 | 49.75 | 23.50 | 9.13 | Lever | A22 |
| | | 4 | W3MM4200U | DL442W7 | 13783.00 | | 100,000 | 62.75 | 23.50 | 9.13 | Lever | A23 |
| | 400 | 1 | W3MM1400 ^④ | DL143W7 | 8901.00 | JXD22B400 Factory inst. | 42,000 | 57.00 | 26.00 | 8.66 | Lever | A24 |
| | 400 | 2 | W3MM2400 | — | 16369.00 | JXD22B400 Factory inst. | 42,000 | 70.38 | 23.00 | 9.69 | Lever | A26 |

① Dimensions shown are representative of outside box dimensions and do not include allowances for mounting bumps, hubs, or hardware protrusions.
 ② Accepts 3-pole 100amp maximum circuit breaker.

③ Max. AIC determined by maximum AIC of tenant breakers used in conjunction with meter socket. Higher ratings may be achieved overall thru approved series rating combinations.

④ Alternate trip amperages available. To order, add -amperage after catalog number (350amp becomes W3MM1400-350). List price remains the same. 1 high units only.
 ⑤ Accepts 2-pole 100A max plug-in breaker.

Group Metering