


# Meter Centers

## Commercial Meter Modules: K Base Bolt-In<sup>④</sup> Meter Modules

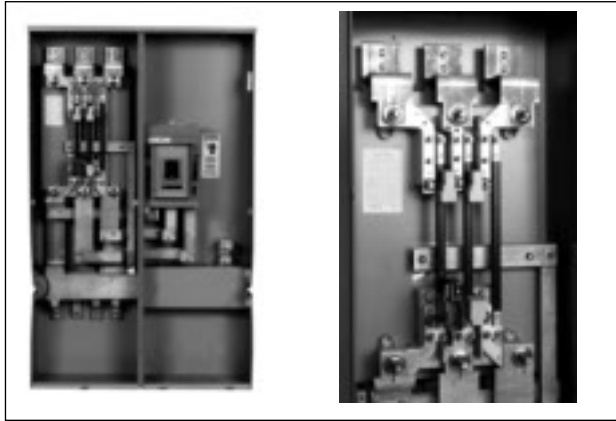

### Features

- All modules feature the Landis & Gyr K5 (single phase) or K7 (three phase) Bolt-on Meter Base
- 22,000 AIC Rating

**Note:** Users are advised to contact utility PRIOR to installation to verify approval. User assumes all responsibility for ensuring utility acceptance prior to installation.

### 1-Phase, 3-Wire SN, Incoming and Outgoing, Ringless Type Lever Bypass Gangable Meter Stacks

Thru-Bus Rating (amps)	Max Tenant Breaker (amps)	Meter Positions Per Stack	Catalog Number	List Price \$	Breaker Provision	Maximum AIC <sup>③</sup>	Dimensions <sup>①</sup>			Stack Phasing: Phases/Socket	KO Fig.
							Height	Width	Depth		
<b>1-Phase 5 Terminal Landis &amp; Gyr K5 Bolt-In Socket, 1 Phase-3 Wire Thru-Bus 120/240V AC Max.-No Bypass</b>											
1200	400	1	W1MM1400B	10681.00	JXD22B400 Factory inst.	22,000	47.94	29.83	8.66	—	A25

### 3-Phase, 4-Wire SN, Incoming and 1-Phase, 3-Wire SN Outgoing, Ringless Type Lever Bypass Gangable Meter Stacks

Thru-Bus Rating (amps)	Max Tenant Breaker (amps)	Meter Positions Per Stack	Catalog Number	List Price \$	Breaker Provision	Maximum AIC <sup>③</sup>	Dimensions <sup>①</sup>			Stack Phasing: Phases/Socket	KO Fig.
							Height	Width	Depth		
<b>1-Phase 5 Terminal Landis &amp; Gyr K5 Bolt-In Socket, 1 Phase-3 Wire Thru-Bus 120/240V AC Max.-No Bypass<sup>②</sup></b>											
1200	400	1	W2MM1400BAB	10681.00	JXD22B400 Factory inst.	22,000	47.94	29.83	8.66	1-AB	A25

### 3-Phase, 4-Wire SN, Incoming and Outgoing, Ringless Type Lever Bypass Gangable Meter Stacks

Thru-Bus Rating (amps)	Max Tenant Breaker (amps)	Meter Positions Per Stack	Catalog Number	List Price \$	Breaker Provision	Maximum AIC <sup>③</sup>	Dimensions <sup>①</sup>			Stack Phasing: Phases/Socket	KO Fig.
							Height	Width	Depth		
<b>3-Phase 7 Terminal Landis &amp; Gyr K7 Bolt-In Socket, 3 Phase-4 Wire Thru-Bus 240V AC Max.-No Bypass</b>											
1200	400	1	W3MM1400B <sup>④</sup>	10681.00	JXD22B400 Factory inst.	22,000	47.94	29.83	8.66	—	A25

① Dimensions shown are representative of outside box dimensions and do not include allowances for mounting bumps, hubs, or hardware protrusions.

② Not for use on 3 phase-4 wire delta systems.

③ Maximum AIC determined by maximum AIC of tenant breakers when used in conjunction with a meter socket. Higher ratings may be achieved thru approved series rating combinations.

④ Alternate trip amperages available. To order, add -amperage after catalog number (350amp becomes W3MM1400-350). List price remains the same. Lead time applies.