


Standby Power Systems

Standby Generators

7 through 150 kW
 1-Phase, 120/240 Volts AC
 3-Phase, 120/208 Volts AC
 3-Phase, 277/480 Volts AC

Features and Ratings

- UL 2200 Listed
- Natural gas or liquid propane vapor options
- Composite mounting pad provided on air cooled units
- Automatic Transfer Switch compatibility:
 Air cooled units compatible with "ST" and "SR" type
 20-60 kW units compatible with "SR" type
 70-150 kW units compatible with "X" type
- 16 kW units and larger are provided with the patented Quiet Test™ feature. This feature allows the generator to run at lower RPM's during the weekly test cycle, greatly reducing noise pollution.
- Rugged, textured paint finish provides superior corrosion resistance
- Aluminum enclosure option ideal for harsh environments

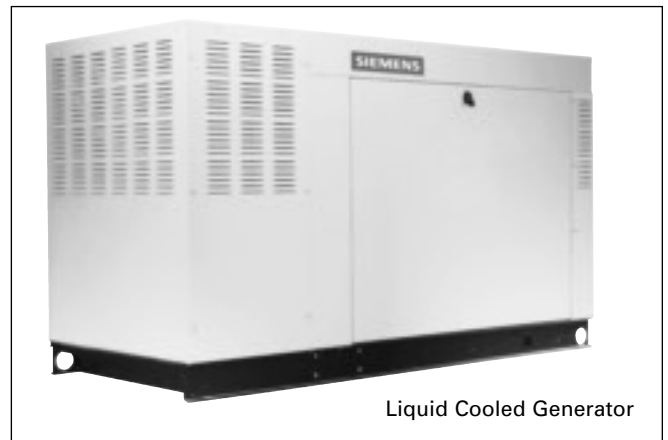

Liquid Cooled Generator



Air Cooled Generator

Catalog Logic Table

	Standby Power Generators	kW Ratings	Voltage	Fuel	Enclosure	Speed
			R=1Ø 120/240V C=3Ø 120/208V J=3Ø 120/240V I=3Ø 277/480V	G=Natural Gas P=Propane B=Both	S=Steel A=Aluminum	Blank=3600 RPM L=1800 RPM
Air Cooled	SG	007	R	B	S	
		010	R	B	S	
		013	R	B	S	
		016	R	B	S, A	
		018	R	B	A	
Liquid Cooled	SG	018	R, C	B	A	L
		020	R, C, J	B	S	
		025	R, C, J	B	S	
		025	R, C, J	B	A	L
		030	R, C, J	B	S	
		035	R, C, J, I	B	A	L
		045	R, C, J, I	B	S	
		045	R, C, J, I	B	A	L
		060	R, C, J, I	G, P	S, A	
		070	R, C, J, I	G, P	S, A	L
		080	R, C, J, I	G, P	S, A	
		100	R, C, J, I	G, P	S, A	
		100	R, C, J, I	G, P	S, A	L
		130	R, C, J, I	G, P	S, A	
		150	R, C, J, I	G, P	S, A	

Generator Information

Dimensions (inches)	Controller Type	Cooling System	Transfer Switch Compatibility
48 x 24 x 29	R	Air	ST, SR
48 x 24 x 29	R	Air	ST, SR
48 x 24 x 29	R	Air	ST, SR
48 x 24 x 29	R	Air	ST, SR
48 x 24 x 29	R	Air	ST, SR
62 x 29 x 33	R	Liquid	SR
72 x 30 x 38	R	Liquid	SR
72 x 30 x 38	R	Liquid	SR
77 x 33 x 45	R	Liquid	SR
77 x 34 x 46	R	Liquid	SR
77 x 33 x 45	R	Liquid	SR
77 x 34 x 46	R	Liquid	SR
77 x 33 x 45	R	Liquid	SR
89 x 34 x 48	H	Liquid	X
77 x 33 x 45	H	Liquid	X
116 x 37 x 55	H	Liquid	X
116 x 37 x 55	H	Liquid	X
116 x 37 x 55	H	Liquid	X
116 x 37 x 55	H	Liquid	X
116 x 37 x 55	H	Liquid	X

Catalog number example

Requirements:

- Standby Generator
- 35 kW
- 3-Phase, 120/208 V~
- Natural Gas
- Aluminum Enclosure

1	2	3	4	5
SG	035	C	B	A

Example = SG035CBA